

TEGUFLEX® W GREEN



**CHEMICALS &
PHARMACEUTICALS**




AUFBAU

Seele: CSM, schwarz.

Decke: CR, schwarz.

Einsatztemperatur: -25 °C bis 90 °C.

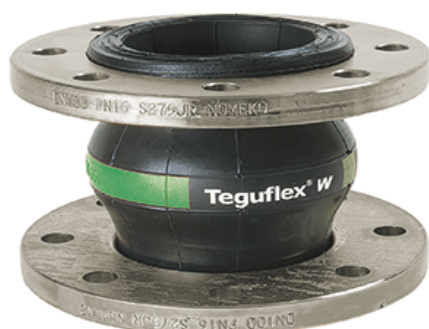

TRELLEBORG IZARRA
IZARRA-ALAVA-SPAIN
Batch number - Working pressure - Testing pressure - T MAX/MIN - DN - Month/Year

CE 0056
MOD: H

TEGUFLEX W



TRELLEBORG

CHEMICALS & PHARMACEUTICALS				TEGUFLEX® W GREEN							
INNEN-Ø mm	PN	BETRIEBS- DRUCK bar	BERST- DRUCK bar	BL m	COMPRESSIO N mm	ELONGATION mm	LATERAL mm	ANGULAR °	WITHOUT SUPPORT RING BAR	ARTIKEL-NR.	LAGER (1) oder MB Stück
25.0	10/16	16	50	150	30	20	20	35	0.8	TW0025GRCR0002	☒
40.0	10/16	16	50	150	30	20	20	35	0.8	0509267	☒
50.0	10/16	16	50	150	30	20	20	35	0.8	0509215	☒
65.0	10/16	16	50	150	30	20	20	30	0.8	0509217	☒
80.0	10/16	16	50	150	30	20	20	30	0.5	0509218	☒
80.0	20	16	50	150	30	20	20	30	0.5	0509219	☒
100.0	10/16	16	50	150	30	20	20	25	0.5	0509220	☒
100.0	20	16	50	150	30	20	20	25	0.5	0509221	☒
125.0	10/16	16	50	150	30	20	20	15	0.5	0509227	☒
150.0	10/16	16	50	150	30	20	20	15	0.5	0509228	☒
150.0	20	16	50	150	30	20	20	15	0.5	0509223	☒
200.0	10	16	50	200	30	20	20	15	0.3	0529229	☒
200.0	16	16	50	200	30	20	20	15	0.3	0508137	☒
250.0	10	16	50	200	30	20	20	10	0.3	0509230	☒
250.0	20	16	50	200	30	20	20	10	0.3	TW0250GRCR0004	☒
300.0	10	16	50	200	30	20	20	10	0.3	0509231	☒
350.0	10	10	30	200	30	20	20	10	0.3	0509232	☒
350.0	16	10	30	200	30	20	20	10	0.3	5011841	☒
400.0	10	10	30	200	30	20	20	10	0.3	0508146	☒
500.0	10	10	30	200	30	20	20	10	0.3	0380326	☒

☒ Je nach Lagerbestand.

Digital version



WWW.TRELLEBORG.COM/FLUIDHANDLING